



W12-3 - The new benchmark

Do you have applications that require sensors to cope with demanding tasks, require higher speeds and can withstand harsh industrial environments? Then W12-3 is the right choice, be it packaging industry, pharmaceutical, food & beverage or bottling industry.

W12-3

- Best optical performance in a metal housing
- PinPoint technology for greater precision
- Flexible connection and simple mounting options
- Reliable detection of glass and transparent films

ECOLAB



For more detailed information, visit www.sick.com.au.

FOR YOUR CHANCE TO WIN AN IPAD - SEE BACK FOR DETAILS.

SICK

Sensor Intelligence.

OUR OCTOBER COMPETITION

Log onto www.sick.com.au to register your name and company details for your chance to win an Apple iPad.

INDUSTRIAL SENSORS



- Photoelectric sensors
- Inductive proximity sensors
- Capacitive proximity sensors
- Magnetic proximity sensors
- Magnetic cylinder sensors

IDENTIFICATION SOLUTION




- Barcode scanners
- Camera based code readers (1D/2D/OCR)
- Mobile hand held scanners
- RFID
- Connection and mounting technology

OPTO-ELECTRONIC PROTECTIVE DEVICES



- Safety Laser
- Laser scanners
- Safety camera systems
- Safety light curtains
- Multiple light beam safety devices

ENCODERS

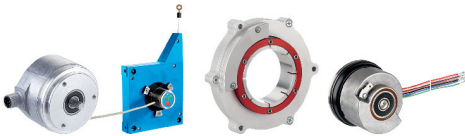

- Motor feedback systems
- Positioning encoders

INDUSTRIAL INSTRUMENTATION



- Level sensors
- Pressure sensors
- Flow sensors
- Temperature sensors

SYSTEM SOLUTIONS



- Volume measurement systems
- Code reading systems
- Hybrid reading systems