


SOW/DWA-FX00402010

AGV Dynamic Weather Assist

SAFETY SYSTEMS FOR OUTDOOR AUTOMATION

SICK
Sensor Intelligence.

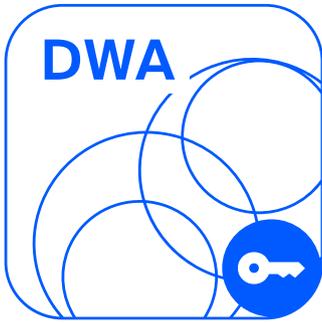

Ordering information

Type	part no.
SOW/DWA-FX00402010	1615375

Other models and accessories → www.sick.com/AGV_Dynamic_Weather_Assist

Detailed technical data

Features

Product type	Software
Items supplied	Software (Safety Designer project file with functional logic) as well as operating instructions
System requirements	The function block requires (at least) one SICK outdoorScan3 Pro – EtherNet/IP™ as well as a SICK Flexi Soft CPU0

Classifications

ECLASS 5.0	27279090
ECLASS 5.1.4	27279090
ECLASS 6.0	27279090
ECLASS 6.2	27279090
ECLASS 7.0	27279090
ECLASS 8.0	27279090
ECLASS 8.1	27279090
ECLASS 9.0	27279090
ECLASS 10.0	27279090
ECLASS 11.0	27279090
ECLASS 12.0	27279090
ETIM 5.0	EC001449
ETIM 6.0	EC001449
ETIM 7.0	EC001449
ETIM 8.0	EC001449
UNSPSC 16.0901	32151705

Certificates

China RoHS	✓
-------------------	---

SICK AT A GLANCE

SICK is one of the leading manufacturers of intelligent sensors and sensor solutions for industrial applications. A unique range of products and services creates the perfect basis for controlling processes securely and efficiently, protecting individuals from accidents and preventing damage to the environment.

We have extensive experience in a wide range of industries and understand their processes and requirements. With intelligent sensors, we can deliver exactly what our customers need. In application centers in Europe, Asia and North America, system solutions are tested and optimized in accordance with customer specifications. All this makes us a reliable supplier and development partner.

Comprehensive services complete our offering: SICK LifeTime Services provide support throughout the machine life cycle and ensure safety and productivity.

For us, that is “Sensor Intelligence.”

WORLDWIDE PRESENCE:

Contacts and other locations –www.sick.com