



YG2A68-400XXXXLECX

Sensor-actuator cables

CONNECTORS AND CABLES

SICK
Sensor Intelligence.



Ordering information

Type	part no.
YG2A68-400XXXLECX	2121385

Other models and accessories → www.sick.com/Sensor-actuator_cables

Illustration may differ



Detailed technical data

Technical specifications

Connection type head A	Female connector, M12, 8-pin, angled, A-coded	
Connection type head B	Flying leads	
Locking plug connector	Screw connection	
Connector material	CuZn	
Locking nut material	Nickel-plated brass	
Seal material	FKM	
Cable	40 m, 8-wire, 8 wires, 4 x 2 twisted in pairs, PUR, halogen-free	
Jacket material	PUR, halogen-free	
Cable diameter	7 mm	
Conductor cross section	0.25 mm ²	
Shielding	Shielded	
Bending radius	Flexible use	> 10 x cable diameter
		> 5 x cable diameter
Bending cycles	> 2,000,000	
Traversing speed	≤ 3.3 m/s	
Acceleration	≤ 5 m/s ²	
Signal type	RS-422, SSI	
Application	Drag chain operation Zones with oils and lubricants	
Enclosure rating	IP67	
Specialty	Very good oil and chemical resistance	
Operating temperature	Flexible use	-25 °C ... +80 °C
		-50 °C ... +80 °C
		-25 °C ... +60 °C
		-25 °C ... +85 °C


Certificates

EU declaration of conformity	✓
UK declaration of conformity	✓
China RoHS	✓

Classifications

ECLASS 5.0	19030312
ECLASS 5.1.4	19030312
ECLASS 6.0	27060304
ECLASS 6.2	27060304
ECLASS 7.0	27060304
ECLASS 8.0	27060304
ECLASS 8.1	27060304
ECLASS 9.0	27060304
ECLASS 10.0	27060304
ECLASS 11.0	27060304
ETIM 5.0	EC000830
ETIM 6.0	EC000830
ETIM 7.0	EC003249
ETIM 8.0	EC003249
UNSPSC 16.0901	26121604

PIN assignment

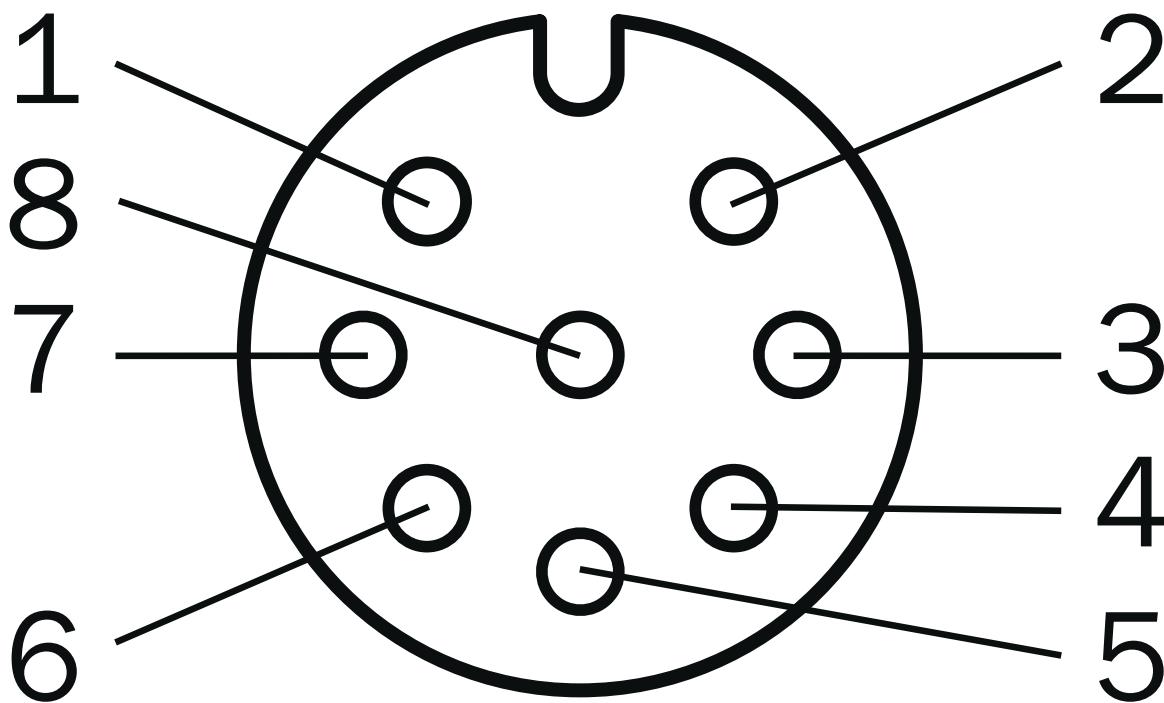

- ① White
- ② Brown
- ③ Green
- ④ Yellow
- ⑤ Gray
- ⑥ Pink
- ⑦ blue
- ⑧ Red

SICK AT A GLANCE

SICK is one of the leading manufacturers of intelligent sensors and sensor solutions for industrial applications. A unique range of products and services creates the perfect basis for controlling processes securely and efficiently, protecting individuals from accidents and preventing damage to the environment.

We have extensive experience in a wide range of industries and understand their processes and requirements. With intelligent sensors, we can deliver exactly what our customers need. In application centers in Europe, Asia and North America, system solutions are tested and optimized in accordance with customer specifications. All this makes us a reliable supplier and development partner.

Comprehensive services complete our offering: SICK LifeTime Services provide support throughout the machine life cycle and ensure safety and productivity.

For us, that is "Sensor Intelligence."

WORLDWIDE PRESENCE:

Contacts and other locations www.sick.com