



Hand-held scanner PROFINET kit

Fieldbus modules

INTEGRATION MODULES AND ADAPTERS

SICK
Sensor Intelligence.



Ordering information

Type	part no.
Hand-held scanner PROFINET kit	1101488

Included in delivery: YMHDAC-C30XXXMDSA9 (1), CDF600-2200 - V2.x, NetX51 (1), CDF600-2200 - V1.x, NetX50 (1)

Other models and accessories → www.sick.com/Fieldbus_modules

Detailed technical data


Features

Accessory group	Fieldbus modules
Description	Connection kit for connecting a hand-held scanner to a PROFINET (Siemens) interface

Classifications

ECLASS 5.0	27242202
ECLASS 5.1.4	27242202
ECLASS 6.0	27242202
ECLASS 6.2	27242202
ECLASS 7.0	27242202
ECLASS 8.0	27242202
ECLASS 8.1	27242202
ECLASS 9.0	27242202
ECLASS 10.0	27242202
ECLASS 11.0	27242202
ECLASS 12.0	27242202
ETIM 5.0	EC001597
ETIM 6.0	EC001597
ETIM 7.0	EC001597
ETIM 8.0	EC001597
UNSPSC 16.0901	32151705

Anschlussschema

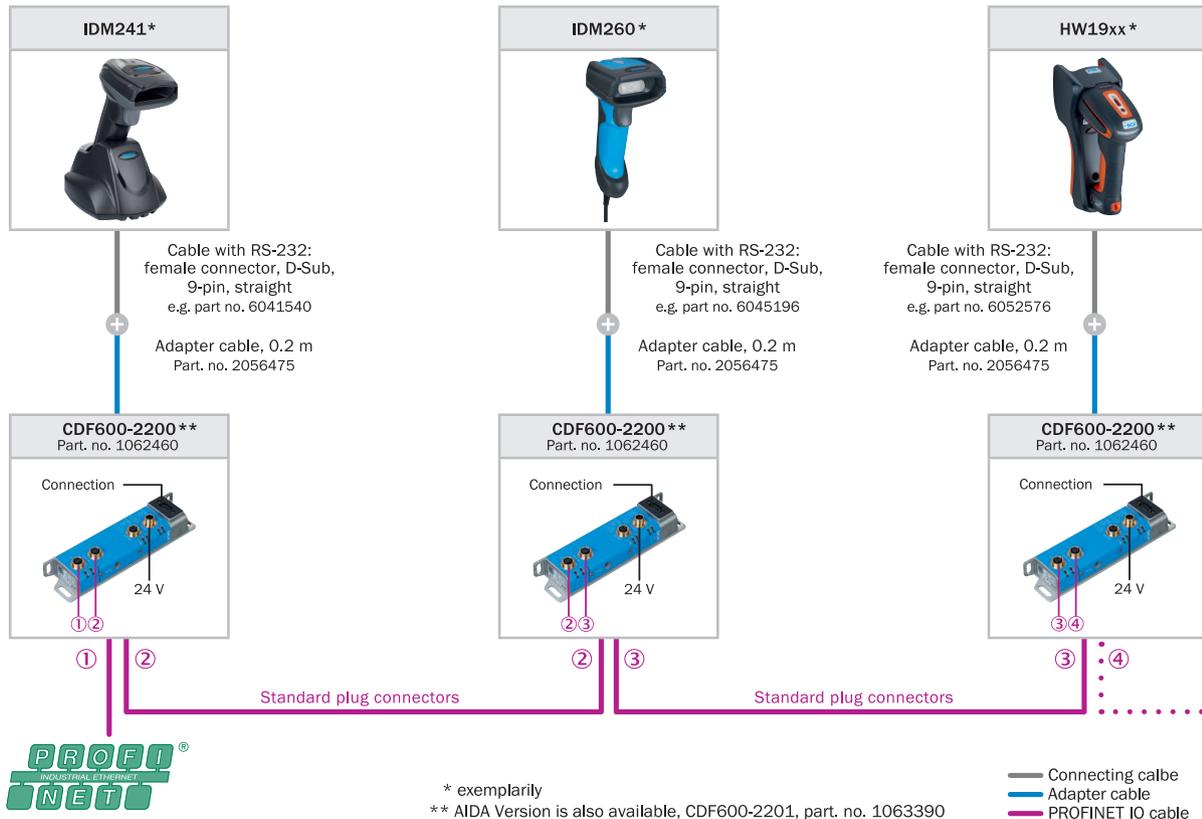

Recommended accessories

Other models and accessories → www.sick.com/Fieldbus_modules

	Brief description	Type	part no.
connectors and cables			
	<ul style="list-style-type: none"> Connection type head A: Female connector, M12, 5-pin, straight, A-coded Connection type head B: Flying leads Signal type: Sensor/actuator cable Cable: 2 m, 5-wire, PUR, halogen-free Description: Sensor/actuator cable, unshielded Application: Drag chain operation, Zones with oils and lubricants, Robot, Drag chain operation 	YF2A15-020UB5XLEAX	2095617
	<ul style="list-style-type: none"> Connection type head A: Male connector, M12, 4-pin, straight, D-coded Connection type head B: Male connector, RJ45, 4-pin, straight Signal type: Ethernet, PROFINET Cable: 2 m, 4-wire, PUR, halogen-free Description: Ethernet, shielded, PROFINET Application: Drag chain operation, Zones with oils and lubricants 	YM2D24-020P-N1MRJA4	2106182

SICK AT A GLANCE

SICK is one of the leading manufacturers of intelligent sensors and sensor solutions for industrial applications. A unique range of products and services creates the perfect basis for controlling processes securely and efficiently, protecting individuals from accidents and preventing damage to the environment.

We have extensive experience in a wide range of industries and understand their processes and requirements. With intelligent sensors, we can deliver exactly what our customers need. In application centers in Europe, Asia and North America, system solutions are tested and optimized in accordance with customer specifications. All this makes us a reliable supplier and development partner.

Comprehensive services complete our offering: SICK LifeTime Services provide support throughout the machine life cycle and ensure safety and productivity.

For us, that is “Sensor Intelligence.”

WORLDWIDE PRESENCE:

Contacts and other locations –www.sick.com